

4 in. Octagonal boxes

Conduit knockouts

01 BCOBEX

Octagonal box extension.

02 BC56111

Ceiling pan.

03 BC54151-K

Concentric knockouts.

04 CI54151-KSSX

Concentric knockouts.
"Wraparound" bracket for
2½ in. and 3⅝ in. steel
studs. With integral
support bracket.

05 BC55151-K

Extension ring with
ground screw.
Concentric knockouts.

06 C54171-K

Concentric knockouts.

07 CI54151-KSSX

Concentric knockouts.
"Wraparound" bracket for
2½ in. and 3⅝ in. steel
studs. With integral
support bracket.

08 CI54171-KSSX-1

Mounting strap
(offset for 2 x ½ in.
drywall thicknesses).

09 CI55171-K

Extension ring with
ground screw,
concentric knockouts.



01



02



03



04



05



06



07



08



09



Cat. No.	Description
½ in. deep – extensions	
BCOBEX	Extension for octagonal boxes. ½ in. non-adjustable depth. Complete with mounting screws (5 cu. in.)

Cat. No.	Volume (Cu. in.)	Features		Knockouts			
		Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	3/4 in. sides	3/4 in. bottom
1/2 in. deep							
BC56111	5.0	–	yes	–	4	–	–
1 1/2 in. deep							
BC54151-K	15.0	–	yes	4	4	2	2
CI54151-KSSX	15.0	“SSX”	yes	2	4	2	2
BC55151-K	15.0	–	yes	4	–	2	–
2 1/8 in. deep							
BC54171-K	21.0	–	yes	4	4	2	2
CI54171-KSSX	21.0	“SSX”	yes	2	4	2	2
CI54171-KSSX-1	21.0	“SSX-1”	yes	2	4	2	2
CI55171-K	21.0	–	yes	4	–	2	–

4 in. Octagonal boxes

Nonmetallic sheathed cable clamps

01 BC54151-L

Prepositioned depth tabs recessed $\frac{1}{2}$ in.

02 BC54151-LB

Side bracket, with holding prongs and prepositioned depth tabs.

03 BC54151-LD

Swing-arm" rework brackets. Max. wall thickness: $\frac{3}{4}$ in., Max. load capacity: 12 lb (5.5 kg).

04 BC54171-L

05 BC54171-LB


Side bracket, with holding prongs.

06 CI54171-LF

Ceiling fan box. (Supplied with 2 #10-32 machine screws and star washers.) Max. load capacity: 35 lb (15.6 kg).



01

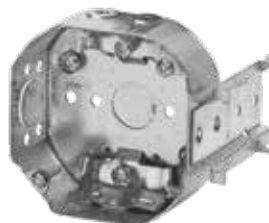

02



03



04



05



06



Cat. No.	Volume (Cu. in.)	Features		Knockouts		Pryouts	
		Bracket	Raised Ground Screw	¹ / ₂ in. sides	¹ / ₂ in. bottom	Sides	Bottom
1 ¹ / ₂ in. deep							
BC54151-L	15.0	–	yes	2	1	4	4
BC54151-LB	15.0	“B”	yes	1	1	4	4
BC54151-LD	15.0	rework	yes	–	1	4	4
CI54151-LF	15.0	–	yes	2	1	4	4
2 ¹ / ₈ in. deep							
BC54171-L	21.0	–	yes	2	1	4	4
BC54171-LB	21.0	“B”	yes	1	1	4	4
BC54171-LD	21.0	rework	–	–	1	4	4
CI54171-LF	21.0	–	yes	2	1	4	4

For use with nonmetallic sheathed cable only.

Note: CEC 2012 rule 30-302: Subrule (4) requires that a ceiling-mounted luminaire weighing 23 kg or less be supported on a ceiling outlet box attached directly to the building structure. A bar hanger may also be used to attach a ceiling outlet box to the building structure when the luminaire weighs 23 kg or less.

4 in. Octagonal boxes

Armoured cable clamps

01 BC54151-LA

02 BC54151-LSSAX
"Wraparound" bracket for
2½ in. and 3-⅝ in. steel
studs. With integral
support bracket.

03 BC54171-LSSAX

04 BC54171-L


05 BC54171-LSSAX-5/8
Brackets for use with
⅝ in. drywall.



01



02

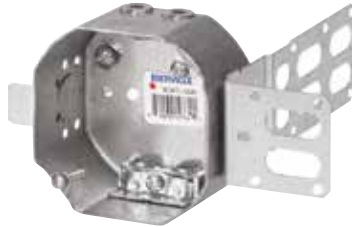

03



04



05



	Volume	Features		Knockouts		Pryouts	
Cat. No.	(Cu. in.)	Bracket	Raised Ground Screw	1/2 in. sides	1/2 in. bottom	Sides	Bottom
1 1/2 in. Deep							
BC54151-LA	15.0	–	yes	2	1	4	–
BC54151-LSSAX	15.0	“SSX”	yes	–	1	4	–
2 1/8 in. Deep							
BC54171-LA	21.0	–	yes	2	1	4	–
BC54171-LSSAX	21.0	“SSX”	yes	–	1	4	–
BC54171-LSSAX-5/8	21.0	“SSX”	yes	–	1	4	–

4 in. Octagonal boxes
Covers



BC54-C-1



BC54-C-6



CI54-C-64



BC54-C-65



BC54-C-94



BC54-COV



BC54-COV-1



Cat. No.	Description
4 in. round covers	
BC54-C-1	Flat blank
BC54-C-6	Flat with 1/2 in. conduit knockout
CI54-C-64	Flat for 1 13/32 in. diameter. 15 A single receptacle. Device mounting screws included
BC54-C-65	Flat for duplex receptacle. Device mounting screw included
BC54-C-94	Flat for toggle switch. Device mounting screws included
5 in. round covers (white enamel paint)	
BC54-COV	Flat with 1/2 in. conduit knockout. Mounting screws included
BC54-COV-1	Flat blank. Mounting screws included