

New product

ERL Series

Vandal resistant linear remote fixture



Features


- Easily adjustable LED strips for multiple beam angles
- 1200-1300 lumen output
- White high impact thermoplastic housing
- Frosted lens
- Impact tested to meet IK10¹
- Standard surface ceiling and wall mount
- Optional accessory: semi-recessed ceiling mount
- Compatible with Emergi-Lite® 12 and 24 volt battery units
- Universal voltage 120V through 347V 60Hz, 12-24VDC
- Rated for -20°C to 45°C
- Suitable for wet locations
- Meets IP65 rating
- ROHS compliant
- cUL approved to CSA C22.2 No, 141-15
- **Warranty details at: www.emergi-lite.ca**

¹IK ratings refer to impact tests. IK10= Protected against 20 joules of impact (equivalent to 5KG of mass dropped from 40cm high)




Dimensions

Dimensions are approximate and subject to change.

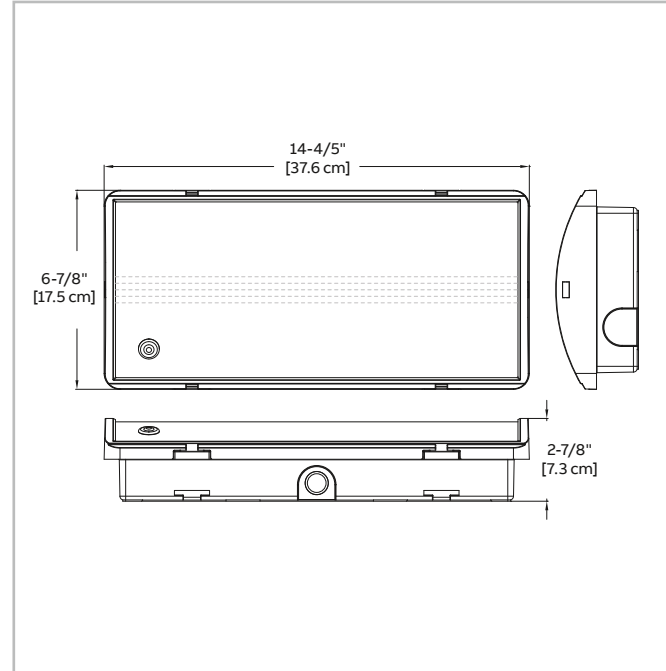

Spacing

| Mounting type | Spacing at 9ft mounting | Lumens |
|----------------------|-------------------------|--------|
| Ceiling mount centre | 62' | 1300 |
| Wall mount | 53' | 1200 |

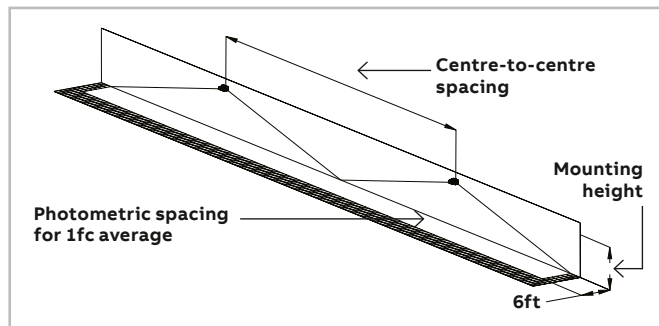

Power consumption

| | Voltage | Wattage |
|----|------------|----------|
| AC | 120-347VAC | 14 watts |
| DC | 12-24VDC | 13 watts |

Accessories (order as a separate item)

| Description | Ordering code |
|--------------------------------|---------------|
| Semi recessed mounting bracket | KIT-SR-E |

Ordering information

| Series | |
|--------------------|----------------------------------|
| ERL= remote linear | -ACDC= ACDC 120-347VAC, 12-24VDC |

Example: ERL-ACDC