

N

new product



CM-Edge Series

Aluminum edge-lit
pictogram sign




FEATURES

- Aluminum frame and polycarbonate panels illuminated by high efficiency LEDs
- Universal side, wall and ceiling mount
- Universal single and double face
- 3 pictogram panels included: 1 with no arrow and 2 with arrows
- 120-347VAC 50/60Hz Input
- Nickel-cadmium battery offering 120 minutes of emergency lighting
- Red LED charger monitor and momentary test switch (self-powered model)
- CSA C22.2 No.141-15 certified

See warranty details at: www.tnb.ca/en/brands/lumacell

DIMENSIONS

Dimensions are approximate and subject to change.

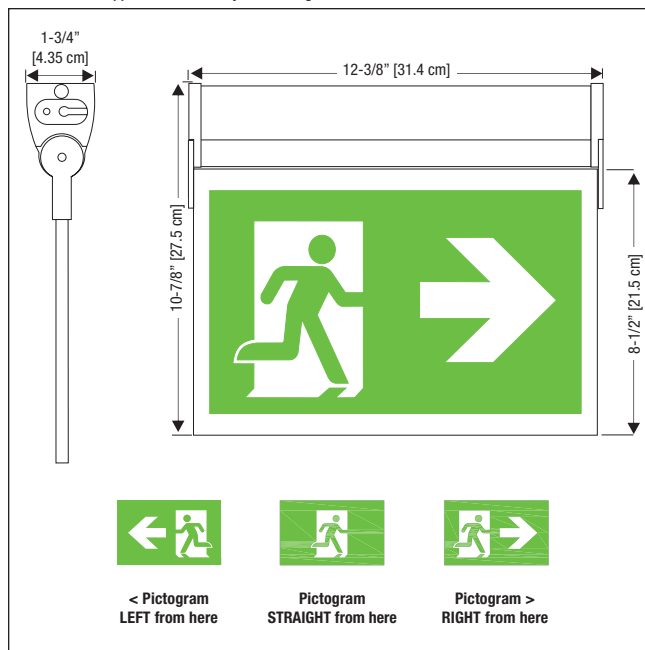

POWER CONSUMPTION AND UNIT RATING

MODEL	AC SPECS			DC SPECS
		WATTAGE (AC/SP)	CURRENT (AC/SP)	
CM-EDGE-L	120V, 50/60Hz	2W/3W	0.01A/0.24A	6 to 24VDC-1W
	277V, 50/60Hz	2W/3W	0.007/0.014A	
	347V, 50/60Hz	3W/4W	0.01A/0.017A	

ORDERING INFORMATION

SERIES	VOLTAGE	BRAND
CM-EDGE	-AC/DC= 6-24VDC, 120-347VAC -SP= 120VAC-347VAC, self-powered (120 minutes)	-L= Lumacell®

EXAMPLE: CM-EDGE-ACDC-L