


DIMENSIONS

Dimensions are approximate and subject to change.

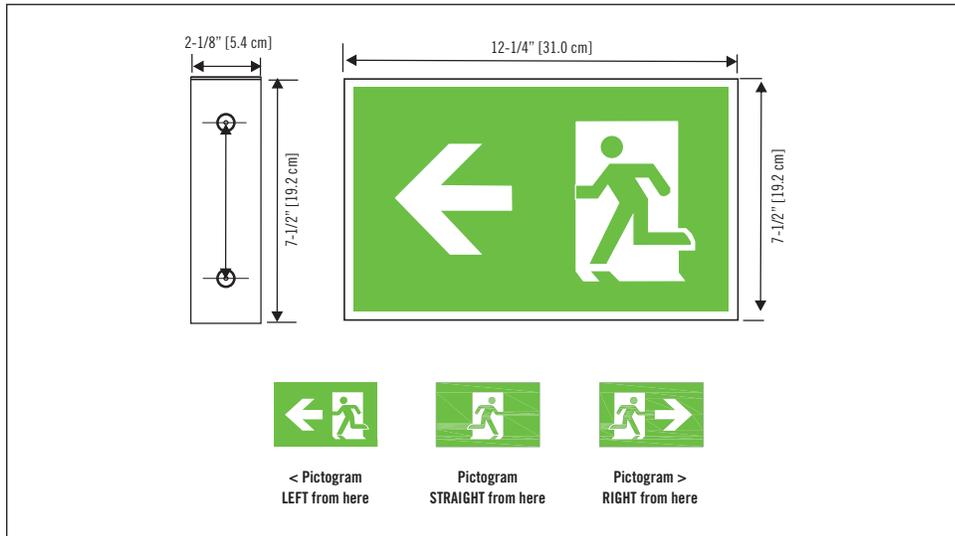

CM-SS SERIES

Steel pictogram sign

FEATURES

- Steel housing and polycarbonate panel illuminated by high efficiency LEDs.
- Universal side, wall and ceiling mount
- Universal single and double face
- 3 pictogram panels included: 1 with no arrow and 2 with arrows
- 120-347VAC 50/60HZ, 6-24VDC input
- Nickel-cadmium battery offering 120 minutes of emergency lighting
- Red LED charger monitor and momentary test switch (self-powered model)
- CSA C22.2 No.141-15 certified

See warranty details at: www.tnb.ca/en/brands/ready-lite

POWER CONSUMPTION AND UNIT RATING

MODEL	AC SPECS			DC SPECS	
		WATTAGE	CURRENT		EFFICIENCY
CM-SS-RL	120V, 50/60Hz	2W/3W	0.01A/0.02A	0.96P/0.98PF	6-24VDC-1W
	277V, 50/60Hz	2.1/3.2W	0.009A/0.013A	0.88PF/0.9PF	
	347V, 50/60Hz	3W/4W	0.01A/0.017A	0.91P/0.92PF	

ORDERING INFORMATION

SERIES	VOLTAGE	BRAND
CM-SS	-ACDC= 120VAC-347VAC, 6-24VDC -SP= 120VAC-347VAC, self-powered (120 minutes)	-RL= Ready-Lite®

EXAMPLE: CM-SS-ACDC-RL