

WP Series

Weatherproof wire connectors



The Marrette WP is a wire connector pre-filled with silicone sealant is for use in dry, damp, wet and below or above grade applications.


This ergonomic and easy to use weatherproof wire connector will ensure a fast and reliable connection for a multitude of outdoor applications for the residential and commercial sector.

External cap:

- Connector cap pre-filled with dielectric silicone sealant to create a water, dust and corrosion proof connection saving time and reduce installation cost.
- Winged design for a more ergonomic installation reducing fatigue.
- Made of durable flame-retardant polypropylene resistant to temperatures up to 105°C (221°F).

Inner spring:

- Live action variable volume spring expands to accommodate a wide variety of wire combinations.
- Zinc-plated square wire spring for a firm and secure grip on conductors.
- Wide range of accepted wire combinations: #20 to #8 AWG, solid or stranded.
- Approved for circuits up to 600 V and lighting fixtures and signs up to 1000 V.
- For copper conductor only.

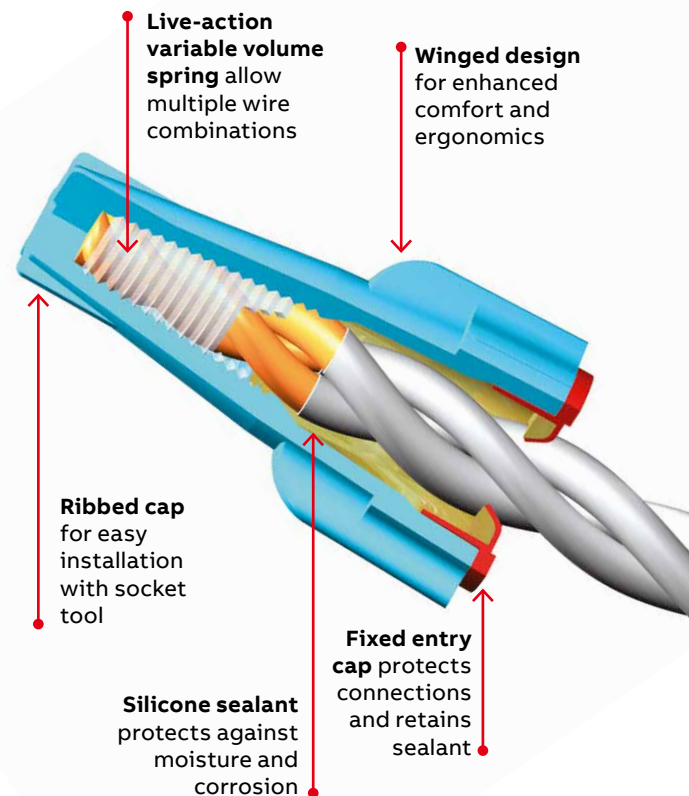

WP Series

Ordering information

| Model | Colour | AWG wire range | | | | | | | |
|-------|------------|----------------|----|----|----|----|----|--------------------------------|---|
| | | 22 | 20 | 18 | 16 | 14 | 12 | 10 | 8 |
| WP33 | Blue/Red | | | | | | | Min. 2 #20, Max. 3 #12 sol/str | |
| WP39 | Blue/Black | | | | | | | Min. 3 #16, Max. 4 #10 sol/str | |

Note: Refer to pages A42-A45 for related wire combination reference guide.

Packaging options



| Cat. no. | Packaging format | Quantity per package | Std. pkg. (min./mult.) |
|-------------|------------------|----------------------|------------------------|
| WP33 | | | |
| WP33M9 | Clamshell | 9 | 90 units |
| WP33B25 | Clamshell | 25 | 250 units |
| WP33JAR150 | Jar | 150 | 1,500 units |

| Cat. no. | Packaging format | Quantity per package | Std. pkg. (min./mult.) |
|-------------|------------------|----------------------|------------------------|
| WP39 | | | |
| WP39M6 | Clamshell | 6 | 60 units |
| WP39B20 | Clamshell | 20 | 200 units |
| WP39JAR100 | Jar | 100 | 1,000 units |