

EAEC Series

Pictogram extruded aluminum edge-lit combo



FEATURES


- Extruded aluminum trim plate
- Universal wall and ceiling surface or recessed mounting
- Includes pictogram panels for single and double face applications
- High power LED lamps
- Lamp heads are fully adjustable
- High temperature long life Ni-MH battery
- 120/347VAC 60Hz
- CSA C22.2 no.141-15 approved
- Standard with diagnostics
- Unit has a one-year limited warranty

See warranty details at:

<http://www.tnb.ca/en/brands/emergi-lite>

PHOTOMETRIC PERFORMANCE

SERIES	SPACING CENTER-TO-CENTER
	7.5 FEET MOUNTING HEIGHT
EAEC-2H0	30 feet

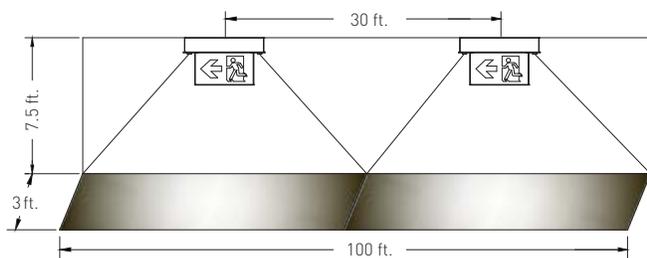

POWER CONSUMPTION

MODEL	AC SPECS		DC SPECS	
EAEC-2H0	120/347VAC, 60 Hz	3W	Ni-MH battery	Minimum 90 minutes

DIMENSIONS

Dimensions are approximate and subject to change.



< PICTOGRAM LEFT FROM HERE




PICTOGRAM STRAIGHT FROM HERE




PICTOGRAM > RIGHT FROM HERE

SURFACE MOUNT

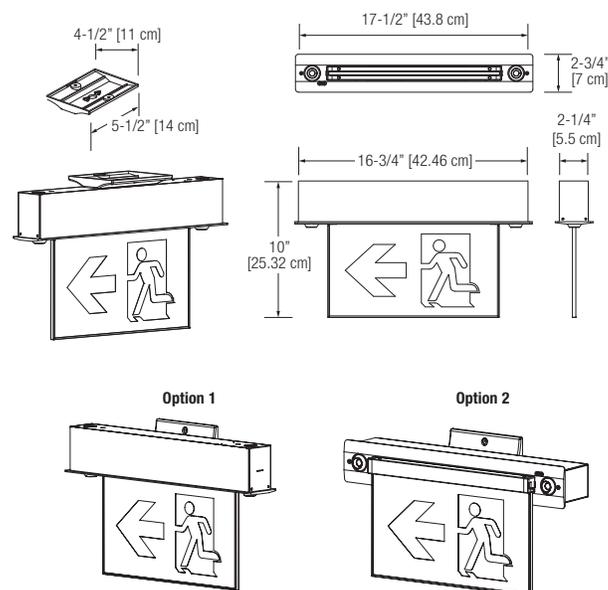

RECESSED MOUNT

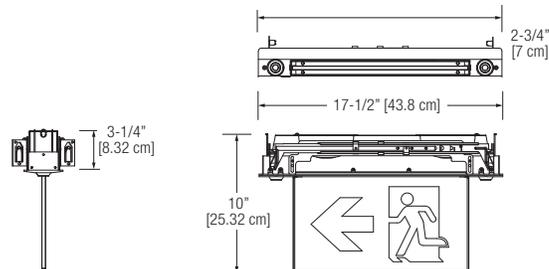

ORDERING INFORMATION

SERIES	FACE/ARROW (UNIVERSAL MOUNTING)	COLOUR	LAMP
EAEC	Blank= Universal faces	Blank= Factory white	-2H0= 2 high output LED lights

EXAMPLE: EAEC-2H0