

CMPC-E Series

Thermoplastic pictogram combo unit



Features

- Energy efficient, long-life white LEDs consuming 4.2W at normal operation
 - Dual voltage input capability 120/347VAC
 - Universal single and double face
 - Automatic, temperature compensated, pulse type charger
 - Low voltage disconnect prevents over discharge of battery
 - Automatic brownout protection
 - Battery lock-out prevents discharge during installation
 - Comes standard with three pictogram legends for direction selection
 - Red LED charger monitor
 - Injection-molded off-white thermoplastic ABS housing
 - Fast and easy installation with snap-together design
 - Ceiling, wall or end mount installation
 - CSA C22.2 no.141-10 listed
 - 3.6V nickel-cadmium battery provides minimum 120 minutes of emergency lighting
 - Fully adjustable LED glare-free lens
 - 3.6V-2W long life LED light source
 - Adjustable light heads for forward or backward lighting
 - Comes standard with one (1) year warranty
- Warranty details at: www.tnb.ca/en/brands/emergi-lite**



Power consumption and unit rating


Series	AC specs			
	Wattage	Current	Efficiency	
CM-PC	120V, 50/60 Hz	2.5W	0.24A	0.98P
	277V, 50/60 Hz	3W	0.014A	0.93P
	347V, 50/60 Hz	3.5W	0.017A	0.92P

Circuitry

Emergency duration	≥ 2 Hours
Recharge time	24 Hours
Output wattage	CM-PC : 1W+2W*2PC
Light Source	Ultra bright LED
Color temperature	6500K- 7500K
Ni-Cd Battery:	CM-PC: 3.6V 1800mAh SC
Product size	415 X 315 X 74/mm

Dimensions

Dimensions are approximate and subject to change.

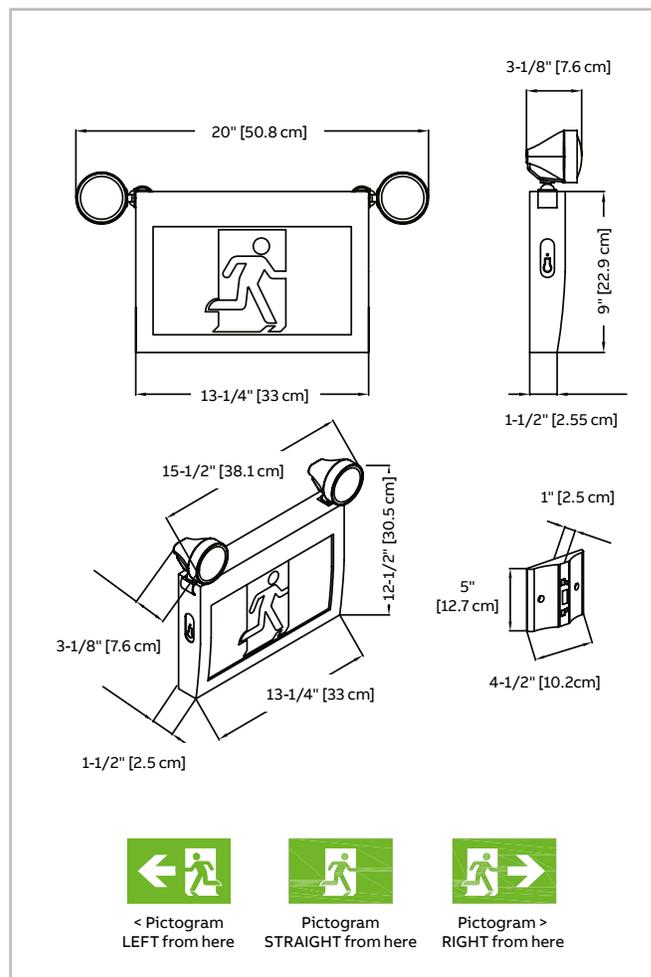

Ordering information

Series	Voltage
CM-PC-E	Blank= 120/347VAC

Example: CM-PC-E