


Coudes de type DB/2



N° de cat.	Gros. nom. (po)	Rayon (po)	Qté/Ctn std
CPF9DJ-PD-RD	2	24	1
CPF9DL-PD-RD	3	24	1
CPF9DN-PD-RD	4	24	1
CPF9DP-PD-RD	5	24	1
CPF9FJ-PD-RD	2	36	1
CPF9FL-PD-RD	3	36	1
CPF9FN-PD-RD	4	36	1
CPF9FP-PD-RD	5	36	1
CPF9FR-PD-RD	6	36	1
CPF9GP-PD-RD	5	42	1
CPF9IJ-PD-RD	2	60	1
CPF9IL-PD-RD	3	60	1
CPF9IN-PD-RD	4	60	1
CPF9IP-PD-RD	5	60	1
CPF9IR-PD-RD	6	60	1
CPF9BJO-PD-RD	2	12	1
CPF9FJO-PD-RD	2	36	1
CPF9FLO-PD-RD	3	36	1
CPF9FNO-PD-RD	4	36	1


Schéma

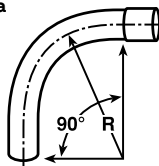

Coudes à 90°

N° de cat.	Gros. nom. (po)	Rayon (po)	Qté/Ctn std
CPF7DJ-PD-RD	2	24	1
CPF7DL-PD-RD	3	24	1
CPF7DN-PD-RD	4	24	1
CPF7FJ-PD-RD	2	36	1
CPF7FL-PD-RD	3	36	1
CPF7FN-PD-RD	4	36	1
CPF7FR-PD-RD	6	36	1
CPF7GP-PD-RD	5	42	1
CPF7IN-PD-RD	4	60	1
CPF7IP-PD-RD	5	60	1
CPF7IR-PD-RD	6	60	1


Schéma

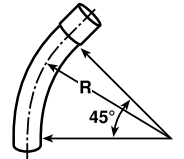

Coudes à 45°

N° de cat.	Gros. nom. (po)	Rayon (po)	Qté/Ctn std
CPF5DJ-PD-RD	2	24	1
CPF5DL-PD-RD	3	24	1
CPF5DN-PD-RD	4	24	1
CPF5FL-PD-RD	3	36	1
CPF5FN-PD-RD	4	36	1
CPF5GP-PD-RD	5	42	1
CPF5IN-PD-RD	4	60	1

Schéma

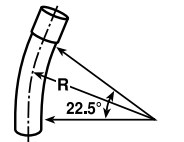

Coudes à 22-1/2°